


DIN 912 similar to ISO 4762

Cylinder screws

Hexagon socket

Steel 10.9 | zinc flake coating | Cr(VI)-free | Metric thread

Further information: DIN-standard has been withdrawn | changed nominal lengths | the fine thread has been transferred to ISO 12474

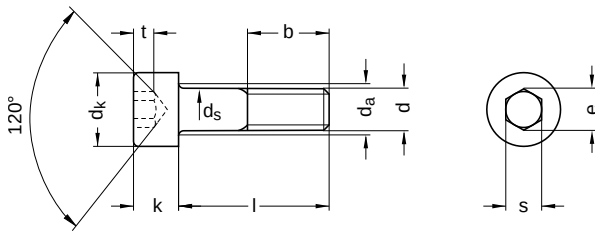

Diameter (d)	b nominal size	da max.	dk		ds		k		e min.	nominal size	s		t min.
			min.	max.	min.	max.	min.	max.					
M 6	24	6.8	9.78	10	5.82	6	5.82	6	5.72	5	5.02	5.14	3
M 8	28	9.2	12.73	13	7.78	8	7.78	8	6.86	6	6.05	6.14	4
M 10	32	11.2	15.73	16	9.78	10	9.64	10	9.15	8	8.02	8.18	5
M 12	36	13.7	17.73	18	11.73	12	11.57	12	11.43	10	10.02	10.18	6
M 16	44	17.7	23.67	24	15.73	16	15.57	16	16.00	14	14.03	14.21	8

nominal size	Length (l)	
	min.	max.
20	19.58	20.42
25	24.58	25.42
30	29.58	30.42
35	34.50	35.50
40	39.50	40.50
50	49.50	50.50

nominal size	Length (l)	
	min.	max.
60	59.40	60.60
80	79.40	80.60
100	99.30	100.70
120	119.30	120.70
130	129.20	130.80
140	139.20	140.80

All technical data refer to the measure mm

