



DIN 934 similar to ISO 4032

Hexagon nuts

External hex

Stainless steel A2 | antiseize as per B 53090 | Cr(VI)-free | Metric thread

Further information: DIN-standard has been withdrawn | changed spanner widths for M10, M12, M14 and M22 | the fine thread has been transferred to ISO 8673

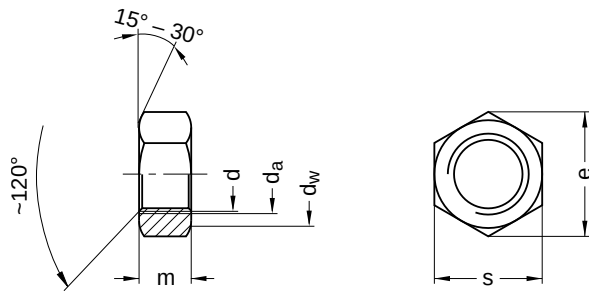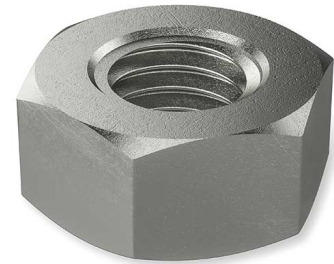

Diameter (d)	d _a		d _w min.	e min.	m		s		Pitch (P)
	min.	max.			min.	max.	min.	max.	
M 8	8	8.75	11.3	14.38	6.14	6.5	12.73	13	1.25
M 10	10	10.80	15.3	18.90	7.64	8.0	16.73	17	1.50
M 12	12	13.00	17.2	21.10	9.64	10.0	18.67	19	1.75
M 16	16	17.30	22.2	26.75	12.30	13.0	23.67	24	2.00

All technical data refer to the measure mm

