




Technical information

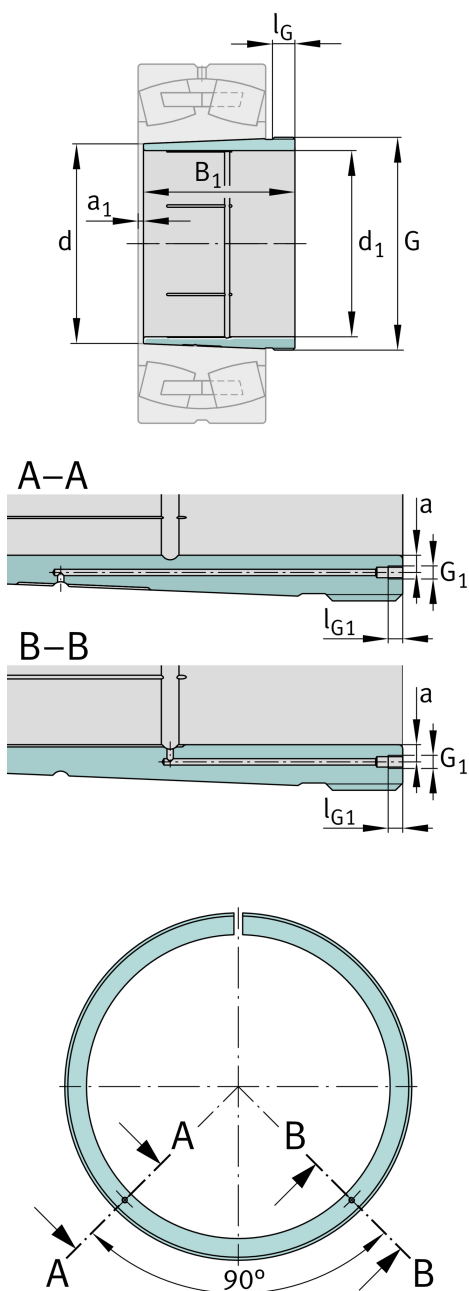

Main Dimensions & Performance Data

|       |           |               |
|-------|-----------|---------------|
| $d_1$ | 220 mm    | bore diameter |
| G     | Tr260X4   | Thread        |
| $B_1$ | 154 mm    | sleeve length |
|       | 12,346 kg | Weight        |

Dimensions

|       |        |                  |
|-------|--------|------------------|
| d     | 240 mm | Bore diameter    |
| $a_1$ | 7 mm   | Bearing overhang |
| $l_G$ | 25 mm  | Thread length    |

Mounting dimensions

|          |        |                            |
|----------|--------|----------------------------|
| $G_1$    | G1/8   | Thread oil connector       |
| a        | 8,5 mm | Distance oil connector     |
| $l_{G1}$ | 12 mm  | Thread depth oil connector |

Additional information

|  |      |       |
|--|------|-------|
|  | 1:12 | Taper |
|--|------|-------|