

FAG

★ 3209-BD-XL



Angular contact ball bearing

Schaeffler ID:
0709376640000Angular contact ball bearing 32..-BD-XL,
double row, X-life, steel sheet metal cage

★ Preferred product

X-life

Technical information

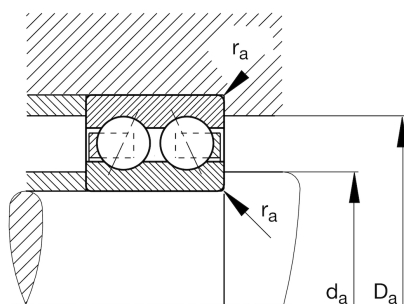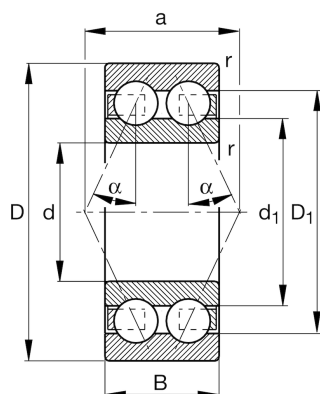

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.
	0,628 kg	Weight

Main Dimensions & Performance Data

d	45 mm	Bore diameter
D	85 mm	Outside diameter
B	30,2 mm	Width
C_r	50.000 N	Basic dynamic load rating, radial
C_{0r}	39.000 N	Basic static load rating, radial
C_{ur}	2.700 N	Fatigue load limit, radial
n_G	8.300 1/min	Limiting speed
n_{gr}	8.400 1/min	Reference speed

Dimensions

r_{min}	1,1 mm	Minimum chamfer dimension
D_1	75,1 mm	Shoulder diameter outer ring
d_1	59,9 mm	Shoulder diameter inner ring
a	50,3 mm	Distance between the apexes of the pressure cones
α	30 °	Contact angle

Mounting dimensions

$d_{a min}$	52 mm	Minimum diameter shaft shoulder
$D_{a max}$	78 mm	Maximum diameter of housing shoulder
$r_{a max}$	1 mm	Maximum fillet radius