



FAG

★ 7213-B-XL-MP


Angular contact ball bearing

Schaeffler ID:
0191153180000Angular contact ball bearing 72..-B-XL-MP,
single row, X-life, solid brass cage

★ Preferred product

X-life

Technical information

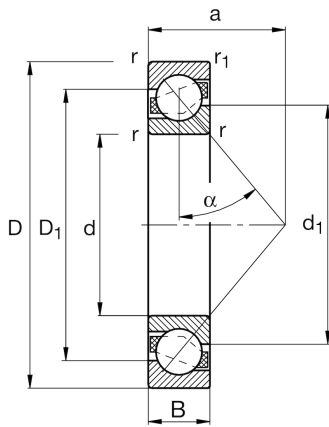

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	150 °C	Operating temperature max.
	1,105 kg	Weight

Main Dimensions & Performance Data

d	65 mm	Bore diameter
D	120 mm	Outside diameter
B	23 mm	Width
C_r	68.000 N	Basic dynamic load rating, radial
C_{0r}	52.000 N	Basic static load rating, radial
C_{ur}	3.600 N	Fatigue load limit, radial
n_G	9.900 1/min	Limiting speed
n_{gr}	5.700 1/min	Reference speed

Dimensions

r_{min}	1,5 mm	Minimum chamfer dimension
$r_{1 min}$	1 mm	Minimum chamfer dimension
D_1	98,9 mm	Shoulder diameter on outer ring wide side face
d_1	86,32 mm	Shoulder diameter on inner ring wide side face
a	51 mm	Distance between the apexes of the pressure cones
α	40 °	Contact angle

Mounting dimensions

$d_{a min}$	74 mm	Minimum diameter of shaft shoulder
$D_{a max}$	111 mm	Maximum diameter of housing shoulder
$D_{b max}$	114,4 mm	Maximaler Durchmesser der Gehäuseschulter
$r_{a max}$	1,5 mm	Maximum fillet radius of shaft
$r_{a1 max}$	1 mm	Maximum fillet radius of housing

