



FAG

## ★ 7222-B-XL-MP


Angular contact ball bearing

Schaeffler ID:  
0191160980000Angular contact ball bearing 72..-B-XL-MP,  
single row, X-life, solid brass cage

★ Preferred product

X-life

## Technical information

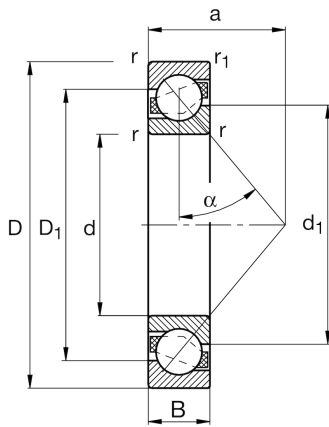

## Temperature range

$T_{min}$	-30 °C	Operating temperature min.
$T_{max}$	150 °C	Operating temperature max.
	4,99 kg	Weight

## Main Dimensions &amp; Performance Data

d	110 mm	Bore diameter
D	200 mm	Outside diameter
B	38 mm	Width
$C_r$	167.000 N	Basic dynamic load rating, radial
$C_{0r}$	154.000 N	Basic static load rating, radial
$C_{ur}$	8.600 N	Fatigue load limit, radial
$n_G$	5.600 1/min	Limiting speed
$n_{gr}$	3.950 1/min	Reference speed

## Dimensions

$r_{min}$	2,1 mm	Minimum chamfer dimension
$r_{1min}$	1,1 mm	Minimum chamfer dimension
$D_1$	165,7 mm	Shoulder diameter on outer ring wide side face
$d_1$	144,9 mm	Shoulder diameter on inner ring wide side face
a	84 mm	Distance between the apexes of the pressure cones
$\alpha$	40 °	Contact angle

## Mounting dimensions

$d_{amin}$	122 mm	Minimum diameter of shaft shoulder
$D_{amax}$	188 mm	Maximum diameter of housing shoulder
$D_{bmax}$	193 mm	Maximaler Durchmesser der Gehäuseschulter
$r_{amax}$	2,1 mm	Maximum fillet radius of shaft
$r_{a1max}$	1 mm	Maximum fillet radius of housing

