

FAG

★ 7222-B-XL-TVP


Angular contact ball bearing

Schaeffler ID:
0167256460000Angular contact ball bearing 72..-B-XL-
TVP, single row, X-life, plastic cage

★ Preferred product

X-life

Technical information

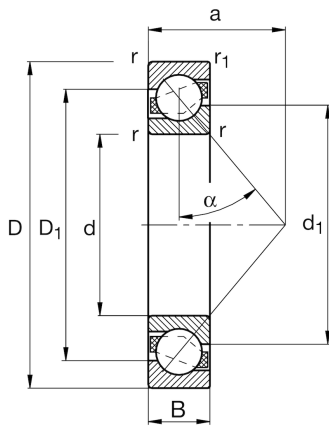

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.
	4,445 kg	Weight

Main Dimensions & Performance Data

d	110 mm	Bore diameter
D	200 mm	Outside diameter
B	38 mm	Width
C_r	167.000 N	Basic dynamic load rating, radial
C_{0r}	154.000 N	Basic static load rating, radial
C_{ur}	8.600 N	Fatigue load limit, radial
n_G	4.350 1/min	Limiting speed
n_{gr}	3.950 1/min	Reference speed

Dimensions

r_{min}	2,1 mm	Minimum chamfer dimension
$r_{1 min}$	1,1 mm	Minimum chamfer dimension
D_1	165,7 mm	Shoulder diameter on outer ring wide side face
d_1	144,9 mm	Shoulder diameter on inner ring wide side face
a	84 mm	Distance between the apexes of the pressure cones
α	40 °	Contact angle

Mounting dimensions

$d_{a min}$	122 mm	Minimum diameter of shaft shoulder
$D_{a max}$	188 mm	Maximum diameter of housing shoulder
$D_{b max}$	193 mm	Maximaler Durchmesser der Gehäuseschulter
$r_{a max}$	2,1 mm	Maximum fillet radius of shaft
$r_{a1 max}$	1 mm	Maximum fillet radius of housing

