



FAG

## ★ 7316-B-XL-MP


Angular contact ball bearing

Schaeffler ID:  
0167263590000Angular contact ball bearing 73..-B-XL-MP,  
single row, X-life, solid brass cage

★ Preferred product

X-life

## Technical information

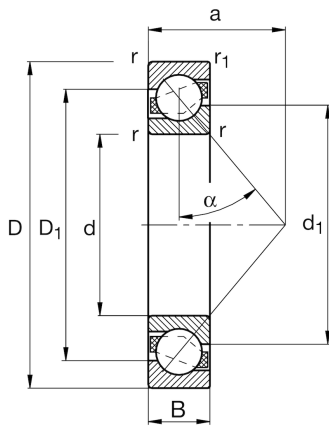

## Temperature range

$T_{\min}$	-30 °C	Operating temperature min.
$T_{\max}$	150 °C	Operating temperature max.
	4,09 kg	Weight

## Main Dimensions &amp; Performance Data

d	80 mm	Bore diameter
D	170 mm	Outside diameter
B	39 mm	Width
$C_r$	155.000 N	Basic dynamic load rating, radial
$C_{0r}$	124.000 N	Basic static load rating, radial
$C_{ur}$	7.700 N	Fatigue load limit, radial
$n_G$	6.800 1/min	Limiting speed
$n_{gr}$	4.250 1/min	Reference speed

## Dimensions

$r_{\min}$	2,1 mm	Minimum chamfer dimension
$r_{1\min}$	1,1 mm	Minimum chamfer dimension
$D_1$	136,7 mm	Shoulder diameter on outer ring wide side face
$d_1$	115,7 mm	Shoulder diameter on inner ring wide side face
a	72 mm	Distance between the apexes of the pressure cones
$\alpha$	40 °	Contact angle

## Mounting dimensions

$d_{a\min}$	92 mm	Minimum diameter of shaft shoulder
$D_{a\max}$	158 mm	Maximum diameter of housing shoulder
$D_{b\max}$	163 mm	Maximaler Durchmesser der Gehäuseschulter
$r_{a\max}$	2,1 mm	Maximum fillet radius of shaft
$r_{a1\max}$	1 mm	Maximum fillet radius of housing

