



FAG

## ★ 7317-B-XL-TVP


Angular contact ball bearing

Schaeffler ID:  
0167264050000Angular contact ball bearing 73..-B-XL-  
TVP, single row, X-life, plastic cage

★ Preferred product

X-life

## Technical information

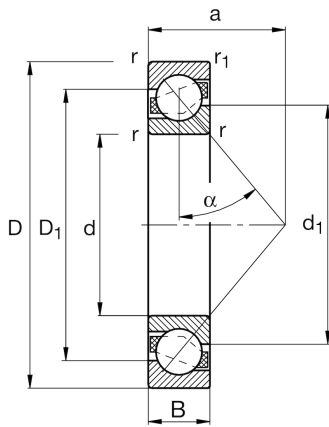

## Temperature range

$T_{\min}$	-30 °C	Operating temperature min.
$T_{\max}$	120 °C	Operating temperature max.
	4,26 kg	Weight

## Main Dimensions &amp; Performance Data

d	85 mm	Bore diameter
D	180 mm	Outside diameter
B	41 mm	Width
$C_r$	167.000 N	Basic dynamic load rating, radial
$C_{0r}$	138.000 N	Basic static load rating, radial
$C_{ur}$	8.300 N	Fatigue load limit, radial
$n_G$	4.900 1/min	Limiting speed
$n_{gr}$	4.100 1/min	Reference speed

## Dimensions

$r_{\min}$	3 mm	Minimum chamfer dimension
$r_{1\min}$	1,1 mm	Minimum chamfer dimension
$D_1$	144 mm	Shoulder diameter on outer ring wide side face
$d_1$	122 mm	Shoulder diameter on inner ring wide side face
a	76 mm	Distance between the apexes of the pressure cones
$\alpha$	40 °	Contact angle

## Mounting dimensions

$d_{a\min}$	99 mm	Minimum diameter of shaft shoulder
$D_{a\max}$	166 mm	Maximum diameter of housing shoulder
$D_{b\max}$	173 mm	Maximaler Durchmesser der Gehäuseschulter
$r_{a\max}$	2,5 mm	Maximum fillet radius of shaft
$r_{a1\max}$	1 mm	Maximum fillet radius of housing

