

FAG



★ 52213

Axial deep groove ball bearing

Schaeffler ID:
0167155600000Axial deep groove ball bearing 522, double
direction, steel sheet metal cage

★ Preferred product

Technical information

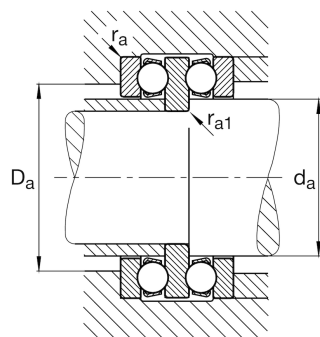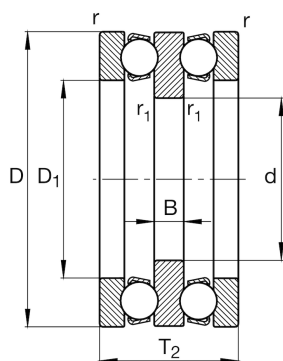

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	150 °C	Operating temperature max.
	1,281 kg	Weight

Main Dimensions & Performance Data

d	55 mm	Bore diameter
D	100 mm	Outside diameter
T_2	47 mm	Height
C_a	64.000 N	Basic dynamic load rating, axial
C_{0a}	149.000 N	Basic static load rating, axial
C_{ua}	6.800 N	Fatigue load limit, axial
n_G	4.100 1/min	Limiting speed
n_{gr}	4.800 1/min	Reference speed

Dimensions

D_1	67 mm	Bore diameter housing washer
B	10 mm	Height shaft washer
r_{min}	1 mm	Minimum chamfer dimension
$r_{1 min}$	0,6 mm	Minimum chamfer dimension

Mounting dimensions

$d_{a max}$	65 mm	Maximum mounting dimension shaft
$D_{a max}$	79 mm	Maximum diameter of housing shoulder
$r_{a max}$	1 mm	Maximum recess radius
$r_{a1 max}$	0,6 mm	Maximum recess radius

Additional information

A	0,14	Minimum load factor
---	------	---------------------