

FAG



★ 52218

Axial deep groove ball bearing

Schaeffler ID:
0167155860000Axial deep groove ball bearing 522, double
direction, steel sheet metal cage

★ Preferred product

Technical information

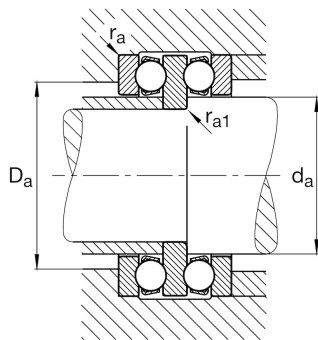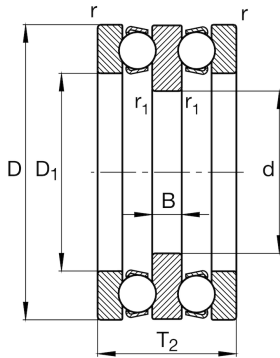

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	150 °C	Operating temperature max.
	3,055 kg	Weight

Main Dimensions & Performance Data

d	75 mm	Bore diameter
D	135 mm	Outside diameter
T_2	62 mm	Height
C_a	119.000 N	Basic dynamic load rating, axial
C_{0a}	300.000 N	Basic static load rating, axial
C_{ua}	13.000 N	Fatigue load limit, axial
n_G	2.900 1/min	Limiting speed
n_{gr}	3.800 1/min	Reference speed

Dimensions

D_1	93 mm	Bore diameter housing washer
B	14 mm	Height shaft washer
r_{\min}	1,1 mm	Minimum chamfer dimension
$r_{1 \min}$	1 mm	Minimum chamfer dimension

Mounting dimensions

$d_{a \max}$	90 mm	Maximum mounting dimension shaft
$D_{a \max}$	108 mm	Maximum diameter of housing shoulder
$r_{a \max}$	1 mm	Maximum recess radius
$r_{a1 \max}$	1 mm	Maximum recess radius

Additional information

A	0,54	Minimum load factor
---	------	---------------------