



FAG

52311

Axial deep groove ball bearing

Schaeffler ID:  
0190070190000Axial deep groove ball bearing 523, double  
direction, steel sheet metal cage

## Technical information

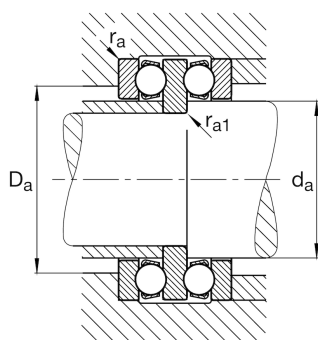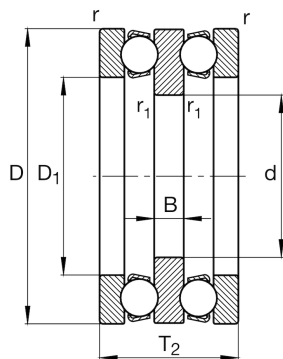

## Temperature range

$T_{\min}$	-30 °C	Operating temperature min.
$T_{\max}$	150 °C	Operating temperature max.
	2,312 kg	Weight

## Main Dimensions &amp; Performance Data

d	45 mm	Bore diameter
D	105 mm	Outside diameter
$T_2$	64 mm	Height
$C_a$	102.000 N	Basic dynamic load rating, axial
$C_{0a}$	207.000 N	Basic static load rating, axial
$C_{ua}$	9.500 N	Fatigue load limit, axial
$n_G$	3.200 1/min	Limiting speed
$n_{gr}$	5.700 1/min	Reference speed

## Dimensions

$D_1$	57 mm	Bore diameter housing washer
B	15 mm	Height shaft washer
$r_{\min}$	1,1 mm	Minimum chamfer dimension
$r_{1 \min}$	0,6 mm	Minimum chamfer dimension

## Mounting dimensions

$d_{a \max}$	55 mm	Maximum mounting dimension shaft
$D_{a \max}$	75 mm	Maximum diameter of housing shoulder
$r_{a \max}$	1 mm	Maximum recess radius
$r_{a1 \max}$	0,6 mm	Maximum recess radius

## Additional information

A	0,26	Minimum load factor
---	------	---------------------