

FAG


★ 4205-BB-TVH

Deep groove ball bearing

Schaeffler ID:
0219434510000Deep groove ball bearing 42...BB-TVH,
double row, plastic cage

★ Preferred product

Technical information

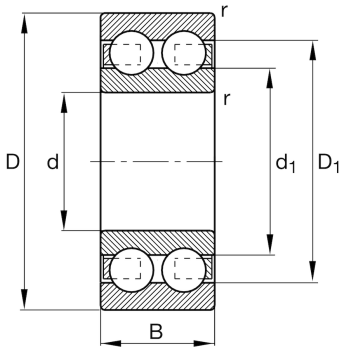

Temperature range

T_{\min}	-20 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	0,159 kg	Weight

Main Dimensions & Performance Data

d	25 mm	Bore diameter
D	52 mm	Outside diameter
B	18 mm	Width
C_r	22.900 N	Basic dynamic load rating, radial
C_{0r}	15.700 N	Basic static load rating, radial
C_{ur}	820 N	Fatigue load limit, radial
n_G	11.100 1/min	Limiting speed
n_{gr}	11.200 1/min	Reference speed

Dimensions

r_{\min}	1 mm	Minimum chamfer dimension
D_1	43,6 mm	Shoulder diameter outer ring
d_1	33,6 mm	Shoulder diameter inner ring

Mounting dimensions

$d_{a\min}$	30,6 mm	Minimum diameter shaft shoulder
$D_{a\max}$	46,4 mm	Maximum diameter of housing shoulder
$r_{a\max}$	1 mm	Maximum fillet radius

Calculation factors

f_0	13,8	Calculation factor
-------	------	--------------------

