

FAG


## ★ 4211-B-TVH

Deep groove ball bearing

Schaeffler ID:  
0167144070000Deep groove ball bearing 42...-B-TVH,  
double row, plastic cage

★ Preferred product

## Technical information

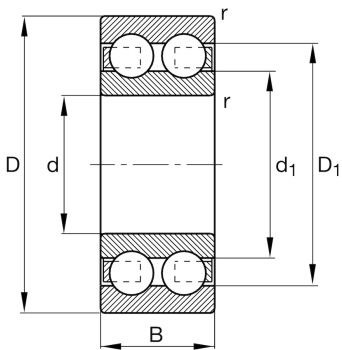

## Temperature range

$T_{min}$	-20 °C	Operating temperature min.
$T_{max}$	120 °C	Operating temperature max.
	0,813 kg	Weight

## Main Dimensions &amp; Performance Data

d	55 mm	Bore diameter
D	100 mm	Outside diameter
B	25 mm	Width
$C_r$	43.000 N	Basic dynamic load rating, radial
$C_{0r}$	42.500 N	Basic static load rating, radial
$C_{ur}$	2.200 N	Fatigue load limit, radial
$n_G$	5.700 1/min	Limiting speed
$n_{gr}$	5.900 1/min	Reference speed

## Dimensions

$r_{min}$	1,5 mm	Minimum chamfer dimension
$D_1$	84,7 mm	Shoulder diameter outer ring
$d_1$	71,4 mm	Shoulder diameter inner ring

## Mounting dimensions

$d_{a min}$	64 mm	Minimum diameter shaft shoulder
$D_{a max}$	91 mm	Maximum diameter of housing shoulder
$r_{a max}$	1,5 mm	Maximum fillet radius

## Calculation factors

$f_0$	15,4	Calculation factor
-------	------	--------------------

