

FAG


★ 4218-B-TVH

Deep groove ball bearing

Schaeffler ID:
0190585510000Deep groove ball bearing 42...-B-TVH,
double row, plastic cage

★ Preferred product

Technical information

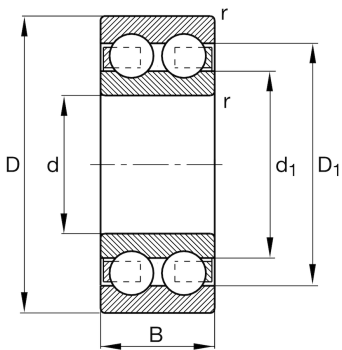

Temperature range

T_{\min}	-20 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	3,15 kg	Weight

Main Dimensions & Performance Data

d	90 mm	Bore diameter
D	160 mm	Outside diameter
B	40 mm	Width
C_r	113.000 N	Basic dynamic load rating, radial
C_{0r}	123.000 N	Basic static load rating, radial
C_{ur}	6.100 N	Fatigue load limit, radial
n_G	3.300 1/min	Limiting speed
n_{gr}	4.100 1/min	Reference speed

Dimensions

r_{\min}	2 mm	Minimum chamfer dimension
D_1	140,2 mm	Shoulder diameter outer ring
d_1	117,6 mm	Shoulder diameter inner ring

Mounting dimensions

$d_{a\min}$	101 mm	Minimum diameter shaft shoulder
$D_{a\max}$	149 mm	Maximum diameter of housing shoulder
$r_{a\max}$	2 mm	Maximum fillet radius

Calculation factors

f_0	15,5	Calculation factor
-------	------	--------------------

