
**FAG**★ **4306-BB-TVH**

Deep groove ball bearing

Schaeffler ID:
0219434270000Deep groove ball bearing 43...BB-TVH,
double row, plastic cage

★ Preferred product

Technical information

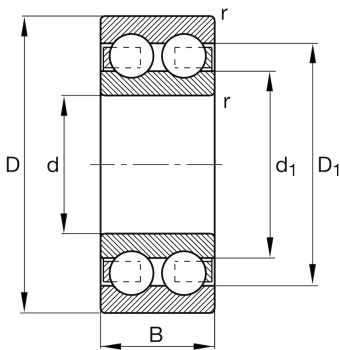

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.
	0,5 kg	Weight

Main Dimensions & Performance Data

d	30 mm	Bore diameter
D	72 mm	Outside diameter
B	27 mm	Width
C_r	44.000 N	Basic dynamic load rating, radial
C_{0r}	30.000 N	Basic static load rating, radial
C_{ur}	1.570 N	Fatigue load limit, radial
n_G	8.000 1/min	Limiting speed
n_{gr}	7.500 1/min	Reference speed

Dimensions

r_{min}	1,1 mm	Minimum chamfer dimension
D_1	59,4 mm	Shoulder diameter outer ring
d_1	42,6 mm	Shoulder diameter inner ring

Mounting dimensions

$d_{a min}$	37 mm	Minimum diameter shaft shoulder
$D_{a max}$	65 mm	Maximum diameter of housing shoulder
$r_{a max}$	1 mm	Maximum fillet radius

Calculation factors

f_0	13	Calculation factor
-------	----	--------------------

