

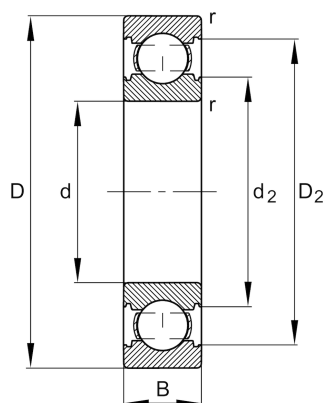
FAG

**6004-C**

Deep groove ball bearing

Schaeffler ID:  
0624298760000Deep groove ball bearing 60..-C, single  
row, Generation C, steel sheet metal cage

## Technical information

**Temperature range**

$T_{\min}$	-30 °C	Operating temperature min.
$T_{\max}$	120 °C	Operating temperature max.
	0,061 kg	Weight

**Main Dimensions & Performance Data**

d	20 mm	Bore diameter
D	42 mm	Outside diameter
B	12 mm	Width
$C_r$	10.600 N	Basic dynamic load rating, radial
$C_{0r}$	5.000 N	Basic static load rating, radial
$C_{ur}$	340 N	Fatigue load limit, radial
$n_G$	27.500 1/min	Limiting speed
$n_{gr}$	19.700 1/min	Reference speed

**Dimensions**

$r_{\min}$	0,6 mm	Minimum chamfer dimension
$D_2$	37,4 mm	Caliber diameter outer ring
$d_2$	25,2 mm	Caliber diameter inner ring

**Mounting dimensions**

$d_{a\min}$	23,2 mm	Minimum diameter shaft shoulder
$D_{a\max}$	38,8 mm	Maximum diameter of housing shoulder
$r_{a\max}$	0,6 mm	Maximum fillet radius

**Calculation factors**

$f_0$	13,8	Calculation factor
-------	------	--------------------

