

FAG



★ 6306-C-2HRS

Deep groove ball bearing

Schaeffler ID:
0791655160000Deep groove ball bearing 63...-C-2HRS,
single row, Generation C, seals, steel
sheet metal cage

★ Preferred product

Technical information

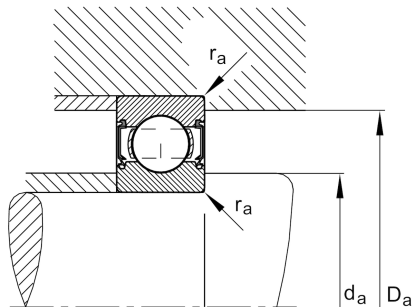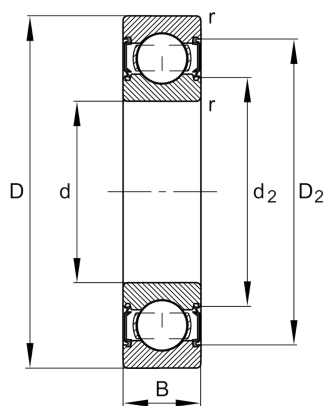

Temperature range

T_{\min}	-20 °C	Operating temperature min.
T_{\max}	110 °C	Operating temperature max.
	0,336 kg	Weight

Main Dimensions & Performance Data

d	30 mm	Bore diameter
D	72 mm	Outside diameter
B	19 mm	Width
C_r	32.000 N	Basic dynamic load rating, radial
C_{0r}	16.200 N	Basic static load rating, radial
C_{ur}	1.120 N	Fatigue load limit, radial
n_G	9.500 1/min	Limiting speed

Dimensions

r_{\min}	1,1 mm	Minimum chamfer dimension
D_2	63,4 mm	Caliber diameter outer ring
d_2	41,3 mm	Caliber diameter inner ring

Mounting dimensions

$d_{a\min}$	37 mm	Minimum diameter shaft shoulder
$D_{a\max}$	65 mm	Maximum diameter of housing shoulder
$r_{a\max}$	1,1 mm	Maximum fillet radius

Calculation factors

f_0	13	Calculation factor
-------	----	--------------------