

FAG

★ QJ307-XL-TVP



Four-point contact bearing

Schaeffler ID:
0167424860000Four point contact bearing QJ3..-XL-TVP,
X-life, plastic cage

★ Preferred product

X-life

Technical information

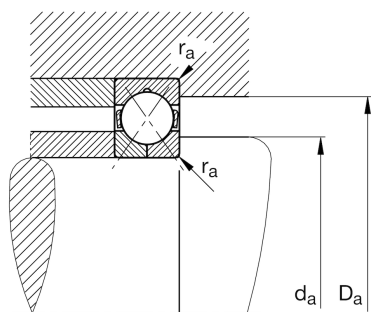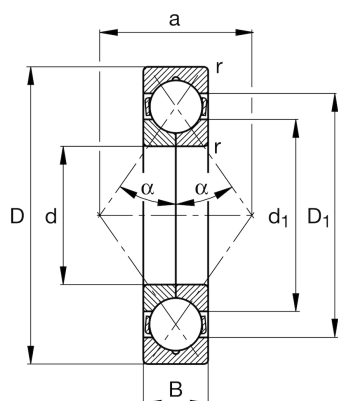

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.
	0,499 kg	Weight

Main Dimensions & Performance Data

d	35 mm	Bore diameter
D	80 mm	Outside diameter
B	21 mm	Width
C_r	65.000 N	Basic dynamic load rating, radial
C_{0r}	51.000 N	Basic static load rating, radial
C_{ur}	3.500 N	Fatigue load limit, radial
n_G	11.900 1/min	Limiting speed
n_{gr}	7.000 1/min	Reference speed

Dimensions

r_{min}	1,5 mm	Minimum chamfer dimension
D_1	64,8 mm	Shoulder diameter outer ring
d_1	50,8 mm	Shoulder diameter inner ring
a	41 mm	Distance between the apexes of the pressure cones
α	35 °	Contact angle

Mounting dimensions

$d_{a min}$	44 mm	Minimum diameter shaft shoulder
$D_{a max}$	71 mm	Maximum diameter of housing shoulder
$r_{a max}$	1,5 mm	Maximum fillet radius