

FAG



★ 2305-2RS-TVH

Self-aligning ball bearing

Schaeffler ID:
0167070010000Self-aligning ball bearing 23...-2RS-TVH,
seals, plastic cage

★ Preferred product

Technical information

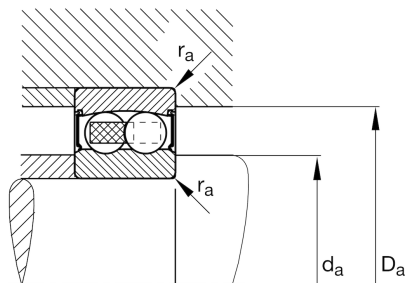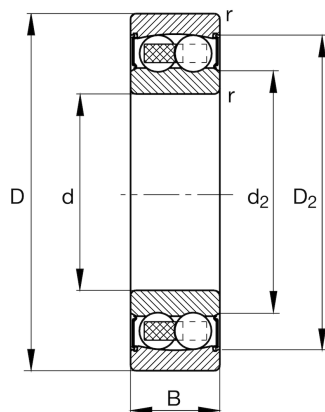

Temperature range

T_{\min}	-20 °C	Operating temperature min.
T_{\max}	100 °C	Operating temperature max.
	0,003 kg	Weight

Main Dimensions & Performance Data

d	25 mm	Bore diameter
D	62 mm	Outside diameter
B	24 mm	Width
r_{\min}	1,1 mm	Minimum chamfer dimension
C_r	18.300 N	Basic dynamic load rating, radial
C_{0r}	5.000 N	Basic static load rating, radial
C_{ur}	320 N	Fatigue load limit, radial
n_G	7.000 1/min	Limiting speed

Dimensions

D_2	52,4 mm	Caliber diameter outer ring
d_2	33,5 mm	Caliber diameter inner ring

Mounting dimensions

$d_{a\min}$	32 mm	Minimum diameter shaft shoulder
$D_{a\max}$	55 mm	Maximum diameter of housing shoulder
$r_{a\max}$	1 mm	Maximum fillet radius

Calculation factors

e	0,28	Limiting value of F_a/F_r for the applicability of diff. Values of factors X and Y
Y_1	2,29	Dynamic axial load factor
Y_2	3,54	Dynamic axial load factor
Y_0	2,4	Static axial load factor