

FAG

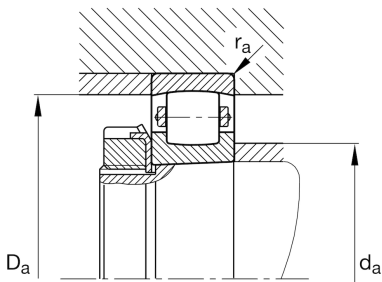
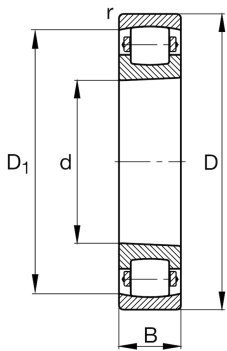
20205-K-TVP-C3

Barrel roller bearing

Schaeffler ID:
0190134850030

Barrel roller bearing 202...-K-TVP

Technical information

**Temperature range**

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	0,133 kg	Weight

Main Dimensions & Performance Data

d	25 mm	Bore diameter
D	52 mm	Outside diameter
B	15 mm	Width
C_r	24.100 N	Basic dynamic load rating, radial
C_{0r}	24.900 N	Basic static load rating, radial
C_{ur}	2.260 N	Fatigue load limit, radial
n_G	11.500 1/min	Limiting speed

Dimensions

r_{\min}	1 mm	Minimum chamfer dimension
D_1	43,9 mm	Bore diameter outer ring

Mounting dimensions

$d_{a \min}$	30,6 mm	Minimum diameter shaft shoulder
$D_{a \max}$	46,4 mm	Maximum diameter of housing shoulder
$r_{a \max}$	1 mm	Maximum recess radius
$d_{a \max}$	33 mm	Maximum diameter of shaft shoulder
$d_{b \min}$	28 mm	Minimum cavity diameter of the sleeve
$B_{a \min}$	6 mm	Minimum cavity width of the sleeve

Additional information

H205	Adapter sleeve
------	----------------