

FAG

★ 20211-K-TVP-C3



Barrel roller bearing

Schaeffler ID:
0384287090030

Barrel roller bearing 202...-K-TVP

★ Preferred product

Technical information

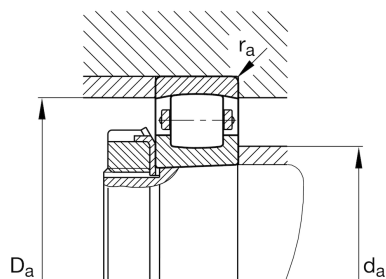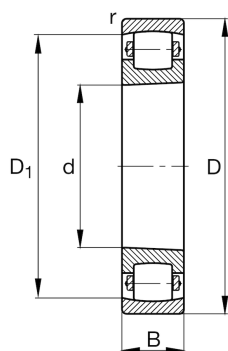

Temperature range

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	120 °C	Operating temperature max.
	0,623 kg	Weight

Main Dimensions & Performance Data

d	55 mm	Bore diameter
D	100 mm	Outside diameter
B	21 mm	Width
C_r	74.000 N	Basic dynamic load rating, radial
C_{0r}	85.000 N	Basic static load rating, radial
C_{ur}	9.000 N	Fatigue load limit, radial
n_G	7.100 1/min	Limiting speed

Dimensions

r_{\min}	1,5 mm	Minimum chamfer dimension
D_1	89,2 mm	Bore diameter outer ring

Mounting dimensions

$d_{a \min}$	64 mm	Minimum diameter shaft shoulder
$D_{a \max}$	91 mm	Maximum diameter of housing shoulder
$r_{a \max}$	1,5 mm	Maximum recess radius
$d_{a \max}$	68 mm	Maximum diameter of shaft shoulder
$d_{b \min}$	60 mm	Minimum cavity diameter of the sleeve
$B_{a \min}$	6 mm	Minimum cavity width of the sleeve

Additional information

H211	Adapter sleeve
------	----------------