

FAG

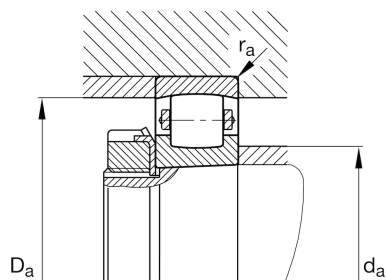
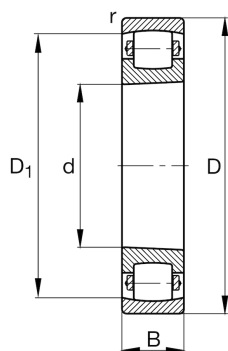
20228-K-MB-C3

Barrel roller bearing

Schaeffler ID:
0380487600030

Barrel roller bearing 202...-K-MB

Technical information

**Temperature range**

T_{\min}	-30 °C	Operating temperature min.
T_{\max}	200 °C	Operating temperature max.
	8,927 kg	Weight

Main Dimensions & Performance Data

d	140 mm	Bore diameter
D	250 mm	Outside diameter
B	42 mm	Width
C_r	395.000 N	Basic dynamic load rating, radial
C_{0r}	540.000 N	Basic static load rating, radial
C_{ur}	51.000 N	Fatigue load limit, radial
n_G	3.050 1/min	Limiting speed

Dimensions

r_{\min}	3 mm	Minimum chamfer dimension
D_1	223,9 mm	Bore diameter outer ring

Mounting dimensions

$d_{a \min}$	154 mm	Minimum diameter shaft shoulder
$D_{a \max}$	236 mm	Maximum diameter of housing shoulder
$r_{a \max}$	2,5 mm	Maximum recess radius
$d_{a \max}$	166 mm	Maximum diameter of shaft shoulder
$d_{b \min}$	147 mm	Minimum cavity diameter of the sleeve
$B_{a \min}$	19 mm	Minimum cavity width of the sleeve

Additional information

H3028	Adapter sleeve
-------	----------------