




## Technical information

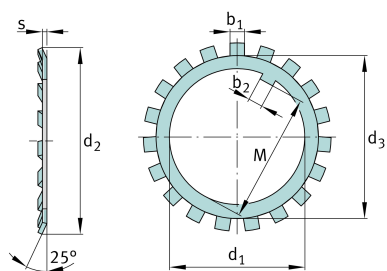

### Main Dimensions & Performance Data

|       |         |                  |
|-------|---------|------------------|
| $d_1$ | 105 mm  | bore diameter    |
| $d_2$ | 145 mm  | Outside diameter |
| $s$   | 1,75 mm | Thickness        |
|       | 81,9 g  | Weight           |

### Dimensions

|  |     |                  |
|--|-----|------------------|
|  | 100 | Counted quantity |
|--|-----|------------------|

### Mounting dimensions

|       |          |                        |
|-------|----------|------------------------|
| $d_3$ | 126 mm   | Plant diameter outside |
| $b_2$ | 12 mm    | Distance lug           |
| $M$   | 100,5 mm | Distance lug           |
| $b_1$ | 12 mm    | Width lock washer tab  |