


HK1522-ZW

Drawn cup needle roller bearing open end

Schaeffler ID:
0001810210000

Drawn cup needle roller bearings with
open ends HK, to DIN 618/ISO 3245

Technical information

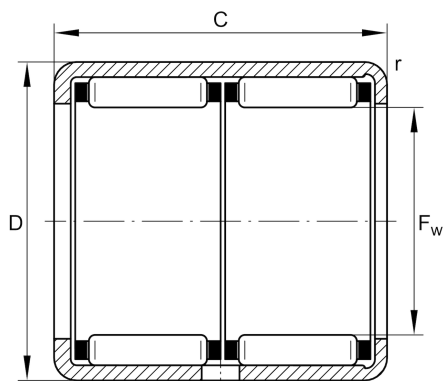

Main Dimensions & Performance Data

F_w	15 mm	Under roller diameter
D	21 mm	Outside diameter
C	22 mm	Width, outer ring
C_r	13.400 N	Basic dynamic load rating, radial
C_{0r}	19.500 N	Basic static load rating, radial
C_{ur}	2.420 N	Fatigue load limit, radial
n_G	16.500 1/min	Limiting speed
n_{gr}	12.300 1/min	Reference speed
	19,675 g	Weight

Additional information

	SD15X21X3	Sealing ring
	G15X21X3	Sealing ring 2
	LR12X15X22,5	Suitable inner rings LR
	IR12X15X22,5-XL	Suitable inner rings IR
r_{min}	0,8 mm	Minimum chamfer dimension

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	140 °C	Operating temperature max.