**NK42/30-XL**

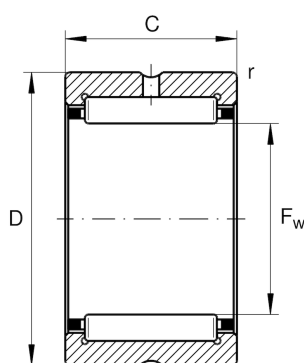
Needle roller bearing

Schaeffler ID:
0507543190000

Needle roller bearings NK, light series

X-life

Technical information

**Main Dimensions & Performance Data**

F_w	42 mm	Under roller diameter
D	52 mm	Outside diameter
C	30 mm	Width, outer ring
C_r	44.500 N	Basic dynamic load rating, radial
C_{0r}	82.000 N	Basic static load rating, radial
C_{ur}	15.500 N	Fatigue load limit, radial
n_G	10.900 1/min	Limiting speed
n_{gr}	6.400 1/min	Reference speed
	0,001 kg	Weight

Additional information

r_{min}	0,3 mm	Minimum chamfer dimension
	G42X52X4	Sealing ring
	SD42X52X4	Sealing ring 2

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.