**NK75/35-XL**

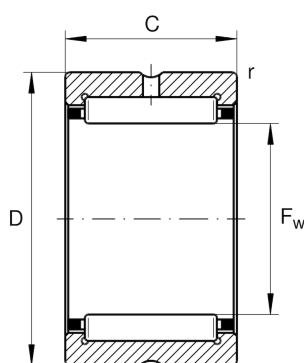
Needle roller bearing

Schaeffler ID:  
0507546370000

Needle roller bearings NK, light series

X-life

## Technical information

**Main Dimensions & Performance Data**

$F_w$	75 mm	Under roller diameter
$D$	92 mm	Outside diameter
$C$	35 mm	Width, outer ring
$C_r$	87.000 N	Basic dynamic load rating, radial
$C_{0r}$	162.000 N	Basic static load rating, radial
$C_{ur}$	28.500 N	Fatigue load limit, radial
$n_G$	6.100 1/min	Limiting speed
$n_{gr}$	3.950 1/min	Reference speed
	0,004 kg	Weight

**Additional information**

$r_{min}$	1 mm	Minimum chamfer dimension
-----------	------	---------------------------

**Temperature range**

$T_{min}$	-30 °C	Operating temperature min.
$T_{max}$	120 °C	Operating temperature max.