

## NKS45-XL


Needle roller bearing

Schaeffler ID:  
0507700630000

Needle roller bearings NKS, heavy series

X-life

### Technical information

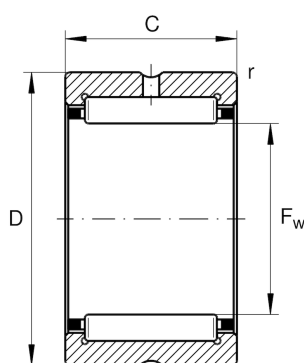

#### Main Dimensions & Performance Data

$F_w$	45 mm	Under roller diameter
$D$	60 mm	Outside diameter
$C$	22 mm	Width, outer ring
$C_r$	45.500 N	Basic dynamic load rating, radial
$C_{0r}$	60.000 N	Basic static load rating, radial
$C_{ur}$	10.600 N	Fatigue load limit, radial
$n_G$	9.800 1/min	Limiting speed
$n_{gr}$	6.000 1/min	Reference speed
	0,001 kg	Weight

#### Additional information

$r_{min}$	0,6 mm	Minimum chamfer dimension
-----------	--------	---------------------------

#### Temperature range

$T_{min}$	-30 °C	Operating temperature min.
$T_{max}$	120 °C	Operating temperature max.