

**RNA4856-XL**

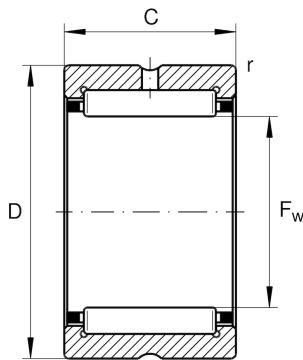
Radial roller bearing

Schaeffler ID:  
0507674450000

Radial roller bearing RNA..-XL

X-life

## Technical information

**Main Dimensions & Performance Data**

$F_w$	305 mm	Under roller diameter
$D$	350 mm	Outside diameter
$B$	69 mm	Width
$C_r$	510.000 N	Basic dynamic load rating, radial
$C_{0r}$	1.300.000 N	Basic static load rating, radial
$C_{ur}$	178.000 N	Fatigue load limit, radial
$n_G$	1.540 1/min	Limiting speed
$n_{G \text{ Grease}}$	930 1/min	Limiting speed for grease lubrication
$n_{gr}$	850 1/min	Reference speed
	9,192 kg	Weight

**Dimensions**

$r_{\min}$	2 mm	Minimum chamfer dimension
$C$	69 mm	Width, outer ring

**Temperature range**

$T_{\min}$	-30 °C	Operating temperature min.
$T_{\max}$	120 °C	Operating temperature max.