

**RNA4913-XL**

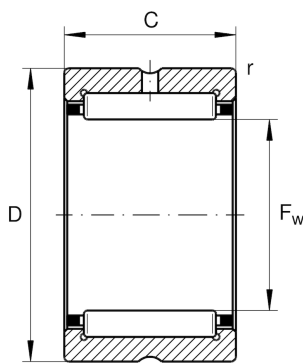
Radial roller bearing

Schaeffler ID:  
0506664600000

Radial roller bearing RNA..-XL

X-life

## Technical information

**Main Dimensions & Performance Data**

$F_w$	72 mm	Under roller diameter
$D$	90 mm	Outside diameter
$B$	25 mm	Width
$C_r$	69.000 N	Basic dynamic load rating, radial
$C_{0r}$	112.000 N	Basic static load rating, radial
$C_{ur}$	19.900 N	Fatigue load limit, radial
$n_G$	6.300 1/min	Limiting speed
$n_{G \text{ Grease}}$	3.800 1/min	Limiting speed for grease lubrication
$n_{gr}$	3.650 1/min	Reference speed
	0,324 kg	Weight

**Dimensions**

$r_{\min}$	1 mm	Minimum chamfer dimension
$C$	25 mm	Width, outer ring

**Temperature range**

$T_{\min}$	-30 °C	Operating temperature min.
$T_{\max}$	120 °C	Operating temperature max.