

RNA4909-RSR-XL


Needle roller bearing

Schaeffler ID:
0507730110000

Needle roller bearings RNA49..-RSR,
dimension series 49, lip seal on one side

X-life

Technical information

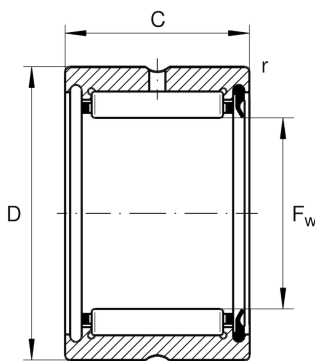

Main Dimensions & Performance Data

F_w	52 mm	Under roller diameter
D	68 mm	Outside diameter
C	22 mm	Width, outer ring
C_r	43.000 N	Basic dynamic load rating, radial
C_{0r}	59.000 N	Basic static load rating, radial
C_{ur}	9.900 N	Fatigue load limit, radial
n_G	5.100 1/min	Limiting speed
	0,002 kg	Weight

Additional information

r_{min}	0,6 mm	Minimum chamfer dimension
-----------	--------	---------------------------

Temperature range

T_{min}	-20 °C	Operating temperature min.
T_{max}	100 °C	Operating temperature max.