

RNAO100X120X30-XL




Needle roller bearing

Schaeffler ID:
0507762070000

Needle roller bearings RNAO, without ribs

X-life

Technical information

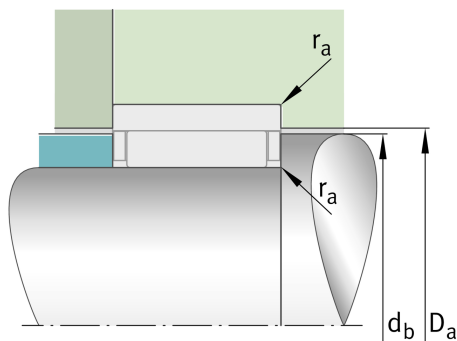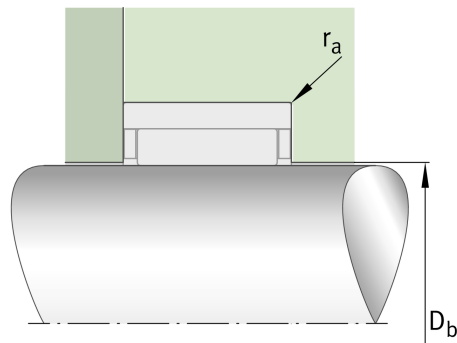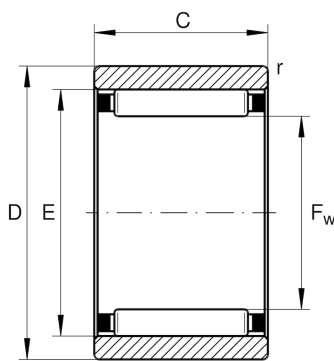

Main Dimensions & Performance Data

F_w	100 mm	Under roller diameter
D	120 mm	Outside diameter
C	30 mm	Width, outer ring
C_r	80.000 N	Basic dynamic load rating, radial
C_{0r}	188.000 N	Basic static load rating, radial
C_{ur}	32.500 N	Fatigue load limit, radial
n_G	4.700 1/min	Limiting speed
n_{gr}	3.150 1/min	Reference speed
	0,694 kg	Weight

Dimensions

E	108 mm	Raceway diameter outer ring
r_{min}	1 mm	Minimum chamfer dimension

Mounting dimensions

D_b	101 mm	Shoulder diameter axial guidance NK/housing
d_b	107,2 mm	Shoulder diameter axial guidance NK/shaft
D_a	109 mm	Shoulder diameter outer ring
$r_{a max}$	1 mm	Maximum recess radius

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.