

RNAO15X23X13-XL



Needle roller bearing

Schaeffler ID:
0507758040000

Needle roller bearings RNAO, without ribs

X-life

Technical information

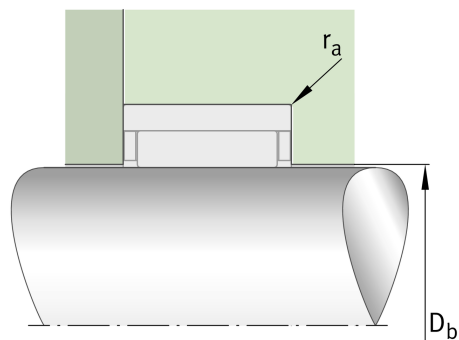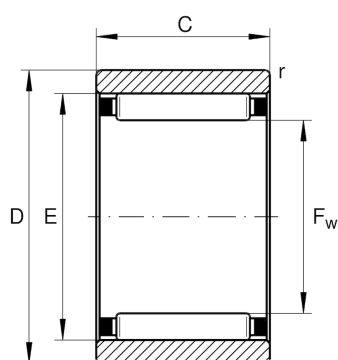

Main Dimensions & Performance Data

F_w	15 mm	Under roller diameter
D	23 mm	Outside diameter
C	13 mm	Width, outer ring
C_r	9.700 N	Basic dynamic load rating, radial
C_{0r}	10.900 N	Basic static load rating, radial
C_{ur}	1.790 N	Fatigue load limit, radial
n_G	24.300 1/min	Limiting speed
n_{gr}	17.900 1/min	Reference speed
	20 g	Weight

Dimensions

E	19 mm	Raceway diameter outer ring
r_{min}	0,3 mm	Minimum chamfer dimension

Mounting dimensions

D_b	15,4 mm	Shoulder diameter axial guidance NK/housing
d_b	18,6 mm	Shoulder diameter axial guidance NK/shaft
D_a	19,3 mm	Shoulder diameter outer ring
$r_{a max}$	0,3 mm	Maximum recess radius

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.