



GAY45-XL-NPP-B


Radial insert ball bearing

Schaeffler ID:
0009432580000

Radial insert ball bearings GAY..-NPP-B, spherical outer ring, location by grub screws, P seals on both sides

X-life

Technical information

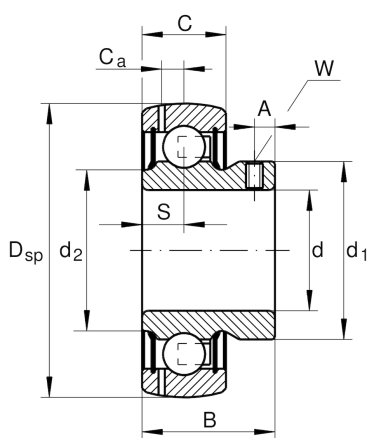

Main Dimensions & Performance Data

d	45 mm	Bore diameter
D _{SP}	85 mm	Outside diameter
B	41,5 mm	Width
n _{G Grease}	9.600 1/min	Limiting speed for grease lubrication
C _r	32.500 N	Basic dynamic load rating, radial
C _{0r}	20.400 N	Basic static load rating, radial
C _{ur}	870 N	Fatigue load limit, radial
	0,57 kg	Weight

Dimensions

C	22 mm	Width, outer ring
S	11 mm	Distance raceway
d ₁	57 mm	Rib diameter inner ring
d ₂	54,3 mm	Rib diameter sealing inner ring
C _a	6,4 mm	Distance to lubrication hole
A	8 mm	Distance thread
W	4 mm	Width of flats

Calculation factors

f ₀	14,1	Calculation factor
----------------	------	--------------------