



IMAGE
COMING SOON




GRA010-NPP-B-AS2/V

Radial insert ball bearing

Schaeffler ID:
0504181650000

Radial insert ball bearing GRA...NPP-B-
AS2/V

Technical information

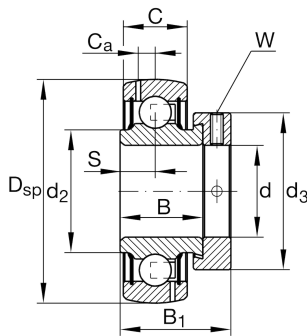

Main Dimensions & Performance Data

d	15,875 mm	Bore diameter
d	0.625 inch	Bore diameter, inch
D _{SP}	40 mm	Outside diameter
B ₁	28,6 mm	Locking collar total width
B	19 mm	Width
C _{ur}	248 N	Fatigue load limit, radial
C _r	10.100 N	Basic dynamic load rating, radial
C _{0r}	4.750 N	Basic static load rating, radial
	0,001 kg	Weight

Dimensions

C	12 mm	Width, outer ring
S	6,5 mm	Distance raceway
d ₂	23 mm	Rib diameter sealing inner ring
C _a	3,4 mm	Distance to lubrication hole
d ₃	28 mm	Outside diameter locking collar/locknut
W	0.125 inch	Width across flats (Inch)

Calculation factors

f ₀	13	Calculation factor
----------------	----	--------------------