




## GRA104-NPP-B-AS2/V

Radial insert ball bearing

Schaeffler ID:  
0502720630000

Radial insert ball bearing GRA...-NPP-B-  
AS2/V

### Technical information

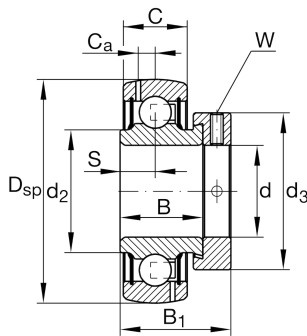

#### Main Dimensions & Performance Data

d	31,75 mm	Bore diameter
d	1.25 inch	Bore diameter, inch
D <sub>SP</sub>	72 mm	Outside diameter
B <sub>1</sub>	39 mm	Locking collar total width
B	25,4 mm	Width
C <sub>ur</sub>	800 N	Fatigue load limit, radial
C <sub>r</sub>	25.500 N	Basic dynamic load rating, radial
C <sub>0r</sub>	15.300 N	Basic static load rating, radial
	0,494 kg	Weight

#### Dimensions

C	19 mm	Width, outer ring
S	9,5 mm	Distance raceway
d <sub>2</sub>	44,5 mm	Rib diameter sealing inner ring
C <sub>a</sub>	5,7 mm	Distance to lubrication hole
d <sub>3</sub>	51 mm	Outside diameter locking collar/locknut
W	0.1875 inch	Width across flats (Inch)

#### Calculation factors

f <sub>0</sub>	13,8	Calculation factor
----------------	------	--------------------