



GRAE45-XL-NPP-B


Radial insert ball bearing

Schaeffler ID:
0008495020000

Radial insert ball bearing GRAE...-XL-NPP-B

X-life

Technical information

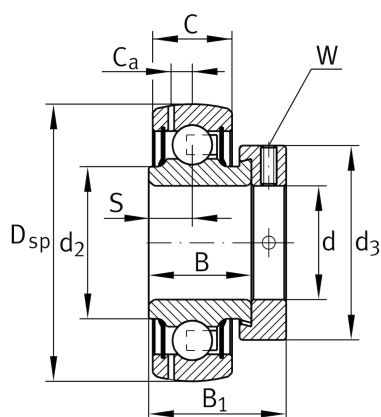

Main Dimensions & Performance Data

d	45 mm	Bore diameter
D _{SP}	85 mm	Outside diameter
B	30,2 mm	Width
B ₁	43,8 mm	Locking collar total width
n _{G Grease}	9.600 1/min	Limiting speed for grease lubrication
C _r	34.500 N	Basic dynamic load rating, radial
C _{0r}	20.400 N	Basic static load rating, radial
C _{ur}	1.060 N	Fatigue load limit, radial
	0,69 kg	Weight

Dimensions

C	22 mm	Width, outer ring
S	11 mm	Distance raceway
d ₂	54,3 mm	Rib diameter sealing inner ring
C _a	6,4 mm	Distance to lubrication hole
d ₃	63 mm	Outside diameter locking collar/locknut
W	5 mm	Width of flats

Calculation factors

f ₀	14,1	Calculation factor
----------------	------	--------------------