

RAE40-XL-NPP-NR


Radial insert ball bearing

Schaeffler ID:
0009732030000

Radial insert ball bearings RAE..-NPP-NR, cylindrical outer ring, location by eccentric locking collar, slots in outer ring, P seals on both sides

X-life

Technical information

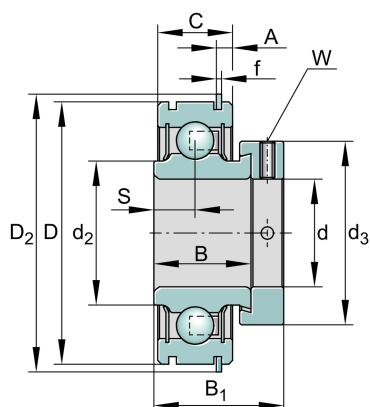

Main Dimensions & Performance Data

d	40 mm	Bore diameter
D	80 mm	Outside diameter
B	30,2 mm	Width
B ₁	43,8 mm	Locking collar total width
C _r	32.500 N	Basic dynamic load rating, radial
C _{0r}	19.800 N	Basic static load rating, radial
C _{ur}	1.030 N	Fatigue load limit, radial
	0,65 kg	Weight

Dimensions

C	21 mm	Width, outer ring
S	11 mm	Distance raceway
d ₂	49,4 mm	Rib diameter sealing inner ring
d ₃	58 mm	Outside diameter locking collar/locknut
A	4,98 mm	Distance snap ring
	0 mm	Upper distance retaining ring tolerance
	-0,3 mm	Lower distance retaining ring tolerance
W	5 mm	Width of flats
D ₂	86,6 mm	Outside diameter snap ring
	0 mm	Upper width snap ring tolerance
	-0,1 mm	Lower width snap ring tolerance

Calculation factors

f ₀	13,6	Calculation factor
----------------	------	--------------------