



IMAGE
COMING SOON



PCJT20-XL-N-FA125


Flanged housing unit

Schaeffler ID:
0096279100000

Housing units PCJT.-FA125, two-bolt
flanged housing units, cast iron, eccentric
locking collar, P seals, with anti-corrosion
protection

X-life

Technical information

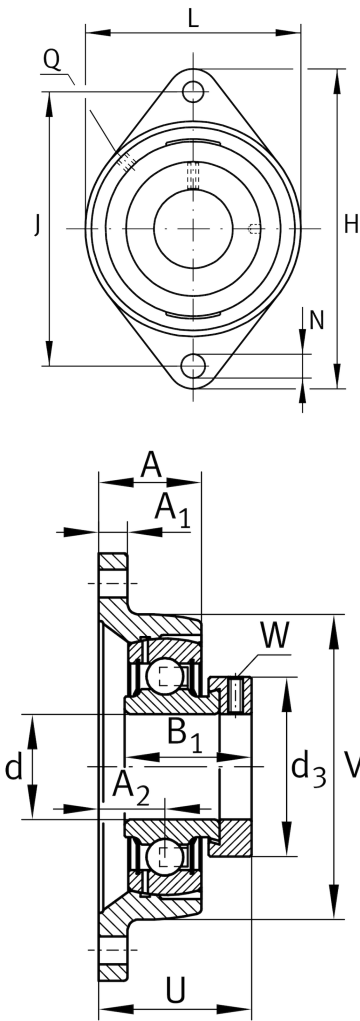

Main Dimensions & Performance Data

d	20 mm	Bore diameter
L	61 mm	Flange width
H	112 mm	Height flange
U	42,5 mm	Total height unit
C _r	13.600 N	Basic dynamic load rating, radial
C _{0r}	6.600 N	Basic static load rating, radial
C _{ur}	345 N	Fatigue load limit, radial
	0,49 kg	Weight

Dimensions

A	28 mm	Height housing
1		Number of housings
A ₁	10 mm	Thickness of flange
A ₂	19 mm	Distance raceway
CJT04		Housing
GRAE20-XL-NPP-B-FA125		Bearing designation
KASK04		Protecting cap
V	61 mm	Shoulder diameter housing
Q	M6	Connection thread lubrication
d ₃	33 mm	Outside diameter eccentric locking collar

Mounting dimensions

J	90 mm	Distance fixing bore
N	11.5 mm	Fixing bore
n	2	Number of screwing holes