




PMEY40-XL-N

Flanged housing unit

Schaeffler ID:
0009400380000

Housing units PMEY, four-bolt flanged housing units, cast iron, centring spigot, grub screws in inner ring, P seals

Technical information

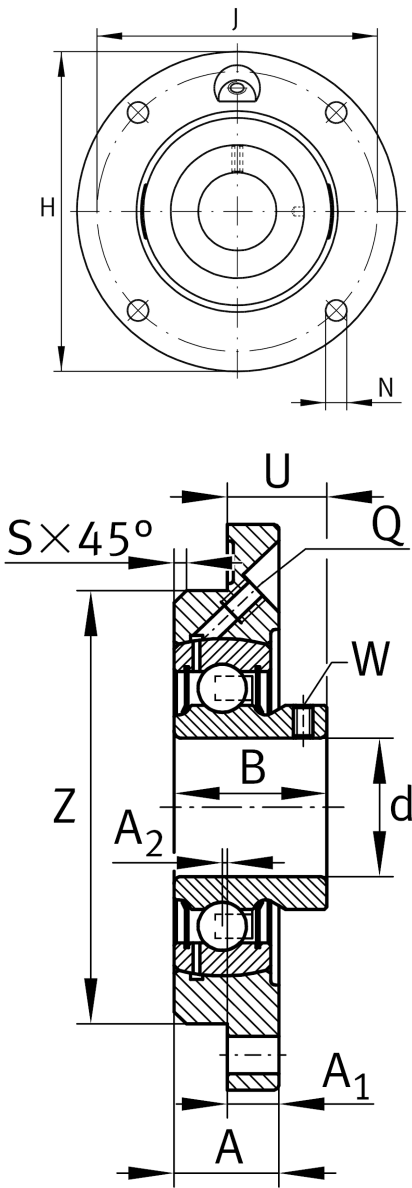

Main Dimensions & Performance Data

d	40 mm	Bore diameter
H	145 mm	Height flange
U	28 mm	Total height unit
C _r	32.500 N	Basic dynamic load rating, radial
C _{0r}	19.800 N	Basic static load rating, radial
C _{ur}	910 N	Fatigue load limit, radial
	1,52 kg	Weight

Dimensions

A	23 mm	Height housing
	1	Number of housings
A ₁	11,5 mm	Thickness of flange
A ₂	1 mm	Distance raceway
	ME08	Housing
	GAY40-XL-NPP-B	Bearing designation
B	39,5 mm	Width
	KASK08	Protecting cap
S	2 mm	Chamfer width
Q	M6	Connection thread lubrication

Mounting dimensions

J	120 mm	Pitch circle diameter (holes)
N	11.5 mm	Fixing bore
Z	100 mm	Diameter spigot
	h8	Diameter spigot clearance
n	4	Number of screwing holes