




PMEY60-XL-N

Flanged housing unit

Schaeffler ID:
0009491160000

Housing units PMEY, four-bolt flanged housing units, cast iron, centring spigot, grub screws in inner ring, P seals

Technical information

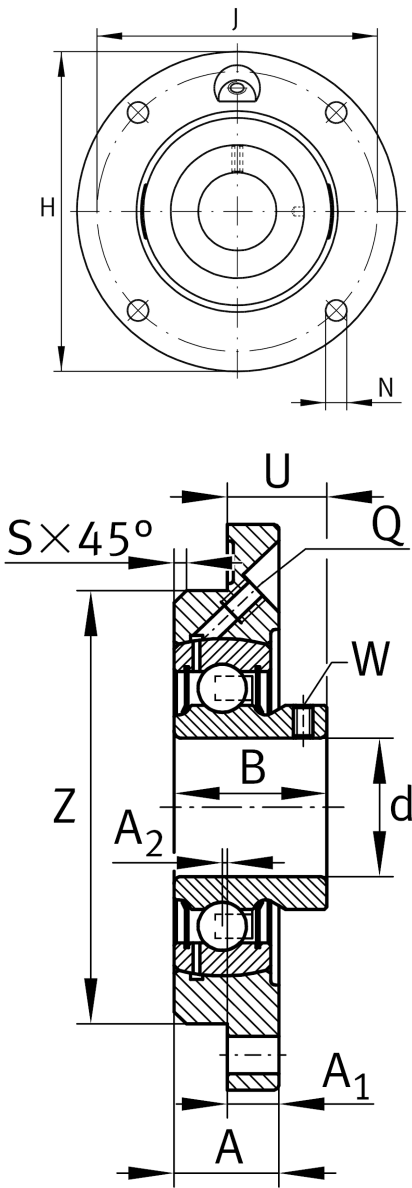

Main Dimensions & Performance Data

d	60 mm	Bore diameter
H	195 mm	Height flange
U	33 mm	Total height unit
C _r	56.000 N	Basic dynamic load rating, radial
C _{0r}	36.000 N	Basic static load rating, radial
C _{ur}	1.530 N	Fatigue load limit, radial
	3,4 kg	Weight

Dimensions

A	29 mm	Height housing
	1	Number of housings
A ₁	16 mm	Thickness of flange
A ₂	1 mm	Distance raceway
	ME12	Housing
	GAY60-XL-NPP-B	Bearing designation
B	47 mm	Width
	KASK12	Protecting cap
S	3 mm	Chamfer width
Q	M6	Connection thread lubrication

Mounting dimensions

J	160 mm	Pitch circle diameter (holes)
N	18 mm	Fixing bore
Z	135 mm	Diameter spigot
	h8	Diameter spigot clearance
n	4	Number of screwing holes