



IMAGE
COMING SOON



RCJT25-XL-N-FA125



Flanged housing unit

Schaeffler ID:
0096281000000

Housing units RCJT...FA125, two-bolt
flanged housing units, cast iron, eccentric
locking collar, R seals, with anti-corrosion
protection

X-life

Technical information

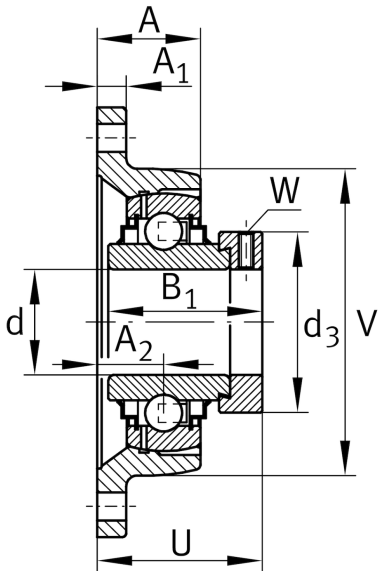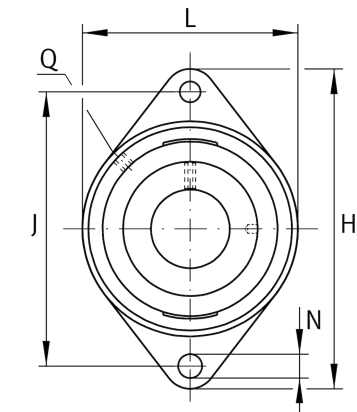

Main Dimensions & Performance Data

d	25 mm	Bore diameter
L	70 mm	Flange width
H	124 mm	Height flange
U	46 mm	Total height unit
C _r	14.900 N	Basic dynamic load rating, radial
C _{0r}	7.800 N	Basic static load rating, radial
C _{ur}	410 N	Fatigue load limit, radial
	0,69 kg	Weight

Dimensions

A	26,5 mm	Height housing
	1	Number of housings
A ₁	11 mm	Thickness of flange
A ₂	19 mm	Distance raceway
	CJT05	Housing
	GE25-XL-KRR-B- FA125	Bearing designation
	KASK05	Protecting cap
V	70 mm	Shoulder diameter housing
Q	Rp1/8	Connection thread lubrication
d ₃	37,5 mm	Outside diameter eccentric locking collar

Mounting dimensions

J	99 mm	Distance fixing bore
N	11.5 mm	Fixing bore
n	2	Number of screwing holes