



IMAGE
COMING SOON



RCJT40-XL-N-FA125


Flanged housing unit

Schaeffler ID:
0096286810000

Housing units RCJT...FA125, two-bolt
flanged housing units, cast iron, eccentric
locking collar, R seals, with anti-corrosion
protection

X-life

Technical information

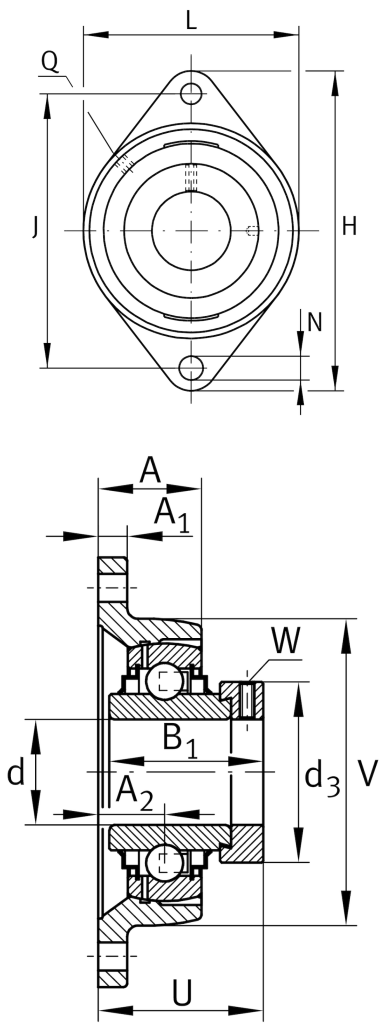

Main Dimensions & Performance Data

d	40 mm	Bore diameter
L	105 mm	Flange width
H	172 mm	Height flange
U	59,1 mm	Total height unit
C _r	32.500 N	Basic dynamic load rating, radial
C _{0r}	19.800 N	Basic static load rating, radial
C _{ur}	840 N	Fatigue load limit, radial
	1,6 kg	Weight

Dimensions

A	34,5 mm	Height housing
1		Number of housings
A ₁	13 mm	Thickness of flange
A ₂	24 mm	Distance raceway
	CJT08	Housing
	GE40-XL-KRR-B-FA125	Bearing designation
	KASK08	Protecting cap
V	105 mm	Shoulder diameter housing
Q	M6	Connection thread lubrication
d ₃	58 mm	Outside diameter eccentric locking collar

Mounting dimensions

J	143,5 mm	Distance fixing bore
N	14 mm	Fixing bore
n	2	Number of screwing holes