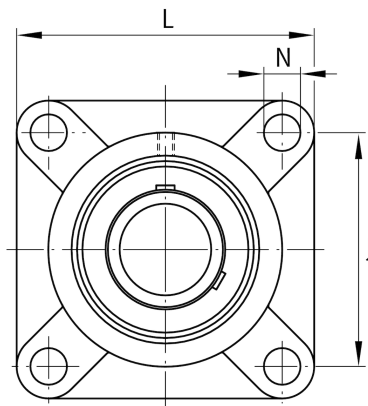
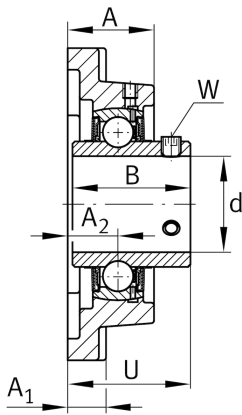
**FAG****UCF212**

Flanged housing unit

Schaeffler ID:
0808222310000

Flanged housing unit UCF

Technical information

**Main Dimensions & Performance Data**

d	60 mm	Bore diameter
L	175 mm	Flange width
U	68,7 mm	Total height unit
C _r	52.000 N	Basic dynamic load rating, radial
C _{0r}	36.000 N	Basic static load rating, radial
C _{ur}	1.530 N	Fatigue load limit, radial
	4,394 kg	Weight

Dimensions

A	48 mm	Height housing
	1	Number of housings
A ₁	20 mm	Thickness of flange
A ₂	29 mm	Distance raceway
	F212	Housing
	UC212	Bearing designation
B	68,7 mm	Width
Q	M6	Connection thread lubrication

Mounting dimensions

J	143 mm	Distance fixing bore
N	19 mm	Fixing bore
N ₁	143 mm	Distance fixing bore
n	4	Number of screwing holes