


## LR200-2RSR

Track roller

Schaeffler ID:  
0034627810000

Track roller LR..-2RSR, single row, no plastic tyre

### Technical information

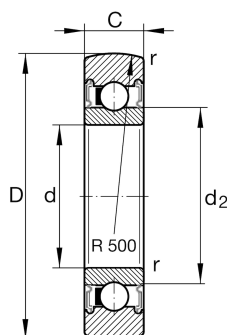

#### Main Dimensions & Performance Data

D	32 mm	Outside diameter
d	10 mm	Bore diameter
C	9 mm	Height
$C_{r w}$	5.100 N	Basic dynamic load rating, radial
$C_{0r w}$	2.380 N	Basic static load rating, radial
$C_{ur w}$	120 N	Fatigue load limit, radial
$n_{DG}$	13.000 1/min	Speed on permanent grease lubrication
	36 g	Weight

#### Dimensions

$d_2$	16,6 mm	Diameter of thrust washer
$r_{min}$	0,6 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile