


LR202-X-2RSR

Track roller

Schaeffler ID:
0899838820000

Track roller LR..-2RSR, single row, no plastic tyre

Technical information

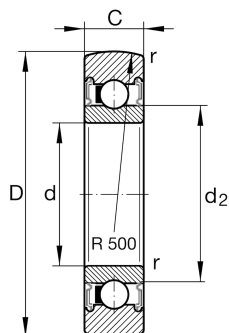

Main Dimensions & Performance Data

D	40 mm	Outside diameter
d	15 mm	Bore diameter
C	11 mm	Height
$C_{r w}$	7.000 N	Basic dynamic load rating, radial
$C_{0r w}$	3.450 N	Basic static load rating, radial
$C_{ur w}$	175 N	Fatigue load limit, radial
n_{DG}	11.000 1/min	Speed on permanent grease lubrication
	0,068 kg	Weight

Dimensions

d_2	21 mm	Diameter of thrust washer
r_{min}	0,6 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile