

## PWTR45-2RS-XL


Yoke type track roller

Schaeffler ID:  
0645551510000

Yoke type track rollers PWTR..-2RS, full complement cylindrical roller set, with axial guidance, lip seals on both sides

X-life

### Technical information

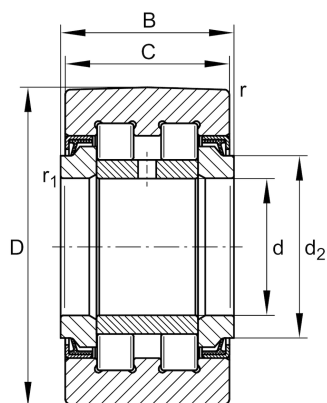

#### Main Dimensions & Performance Data

d	45 mm	Bore diameter
D	85 mm	Outside diameter
B	32 mm	Width, inner ring
$C_{r w}$	45.500 N	Basic dynamic load rating, radial
$C_{0r w}$	64.000 N	Basic static load rating, radial
$C_{ur w}$	8.400 N	Fatigue load limit, radial
$n_{DG}$	1.300 1/min	Speed on permanent grease lubrication
$F_{0r per}$	64.000 N	Permissible static load, radial
$F_{r per}$	41.000 N	Permissible dynamic load outer ring, radial
	0,851 kg	Weight

#### Dimensions

C	30 mm	Width, outer ring
$d_2$	55,2 mm	Stop diameter of thrust washer
$r_{min}$	1,1 mm	Minimum chamfer dimension
$r_{1 min}$	0,6 mm	Minimum chamfer dimension