


RNA2200-2RSR

Yoke type track roller

Schaeffler ID:
0000271970000

Yoke type track rollers RNA22...-2RSR,
without axial guidance, lip seals on both
sides

Technical information

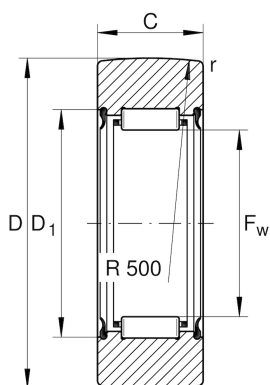

Main Dimensions & Performance Data

D	30 mm	Outside diameter
F _w	14 mm	Under roller diameter
C	13,8 mm	Width, outer ring
C _{r w}	7.000 N	Basic dynamic load rating, radial
C _{0r w}	6.900 N	Basic static load rating, radial
C _{ur w}	1.120 N	Fatigue load limit, radial
n _{D G}	5.500 1/min	Speed on permanent grease lubrication
	52 g	Weight

Dimensions

D _{1 min}	20 mm	Minimum mounting dimension
r _{min}	0,6 mm	Minimum chamfer dimension
R	500 mm	Radius of outer ring outside profile