

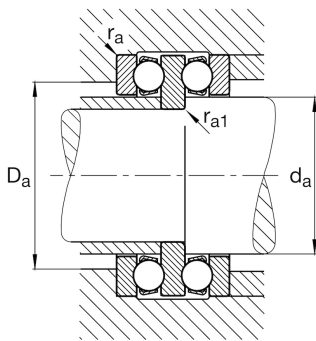
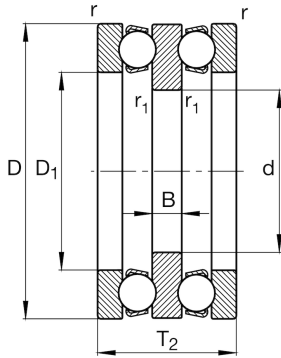
FAG

52410

Axial deep groove ball bearing

Schaeffler ID:
0190070780000Axial deep groove ball bearing 524, double
direction, steel sheet metal cage

Technical information

**Main Dimensions & Performance Data**

d	40 mm	Bore diameter
D	110 mm	Outside diameter
T ₂	78 mm	Height
C _a	138.000 N	Basic dynamic load rating, axial
C _{0a}	255.000 N	Basic static load rating, axial
C _{ua}	11.700 N	Fatigue load limit, axial
n _G	2.650 1/min	Limiting speed
n _{gr}	6.000 1/min	Reference speed
	3,56 kg	Weight

Additional information

D ₁	52 mm	Bore diameter housing washer
B	18 mm	Height shaft washer
r _{min}	1,5 mm	Minimum chamfer dimension
r _{1 min}	0,6 mm	Minimum chamfer dimension

Mounting dimensions

d _{a max}	50 mm	Maximum mounting dimension shaft
D _{a max}	74 mm	Maximum diameter of housing shoulder
r _{a max}	1,5 mm	Maximum recess radius
r _{a1 max}	0,6 mm	Maximum recess radius

Calculation factors

A	0,4	Minimum load factor
---	-----	---------------------

Temperature range

T _{min}	-30 °C	Operating temperature min.
T _{max}	150 °C	Operating temperature max.