

NKS40-XL


Needle roller bearing

Schaeffler ID:
0507700470000

Needle roller bearings NKS, heavy series

X-life

Technical information

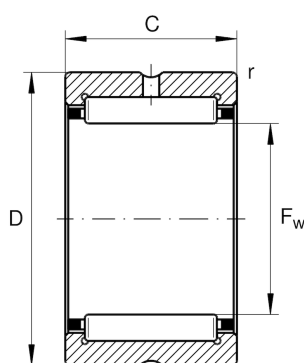

Main Dimensions & Performance Data

F_w	40 mm	Under roller diameter
D	55 mm	Outside diameter
C	22 mm	Width, outer ring
C_r	42.500 N	Basic dynamic load rating, radial
C_{0r}	54.000 N	Basic static load rating, radial
C_{ur}	9.400 N	Fatigue load limit, radial
n_G	10.900 1/min	Limiting speed
n_{gr}	6.600 1/min	Reference speed
	0,001 kg	Weight

Additional information

r_{min}	0,6 mm	Minimum chamfer dimension
-----------	--------	---------------------------

Temperature range

T_{min}	-30 °C	Operating temperature min.
T_{max}	120 °C	Operating temperature max.